



vShape – a flexible and scalable end-to-end Virtual Infrastructure, powered by Fujitsu, Brocade, NetApp and VMWare


The flexible and scalable vShape solution combines all aspects of a virtual environment, based on optimised technologies and best practice solutions, with simple implementation and operation. Customers benefit from validated reference architectures by having a more streamlined, reduced risk experience.

Benefits include:

- Simplified quoting process with a single purchase order
- Reduction of power bills
- Reference architecture mitigates risk of under scoping customer requirements

vShape integrates the technologies of:

- Fujitsu Primergy Servers
- Brocade ICX switches
- NetApp Storage Systems
- VMWare vSphere

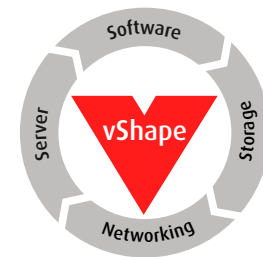

	vShape25 HA	vShape50 HA	vShape100 HA	vShape200 HA
Servers	2x Primergy RX300S8	3x Primergy RX300S8	5x Primergy RX300S8	9x Primergy RX300S8
CPU/Server	Dual Intel XEON E5-2640v2	Dual Intel XEON E5-2660v2	Dual Intel XEON E5-2660v2	Dual Intel XEON E5-2660v2
RAM/Server	96GB	96GB	96GB	96GB
Ethernet	1Gb	1Gb / 10Gb	1Gb / 10Gb	1Gb / 10Gb
Networking	2x Brocade ICX 6430	2x Brocade ICX 6430 / 6610	2x Brocade ICX 6430 / 6610	2x Brocade ICX 6430 / 6610
Storage Model	FAS 2220A	FAS 2240A	FAS 2240A	FAS 2240A
Disk Type	12x 10K SAS 900GB	24x 10K SAS 600GB	48x 10K SAS 600GB	96x 10K SAS 600GB
Usable Capacity	4.4 TB	7.7 TB	17.3 TB	38.5 TB
VMWare Software	Vmware Essentials Plus	vSphere Standard + vCentre Standard	vSphere Standard + vCentre Standard	vSphere Standard + vCentre Standard
Rack (optional)	PRIMECENTER M1 Rack 24U	PRIMECENTER M1 Rack 24U	PRIMECENTER M1 Rack 24U	PRIMECENTER M1 Rack 42U



For more information please contact us on the details below or your local channel account manager.

www.sansystems.com
+61 2 9092 5000
quotes@sansystems.com.au

www.distributioncentral.co.nz
+64 9309 8277
quotes@sansystems.com.au

For more information: info@distributioncentral.com

Sydney | Melbourne | Brisbane | Perth | Canberra | Auckland | Wellington | Singapore